


E30406



Convertor de tensiune

VOLTAGE CONVERTER

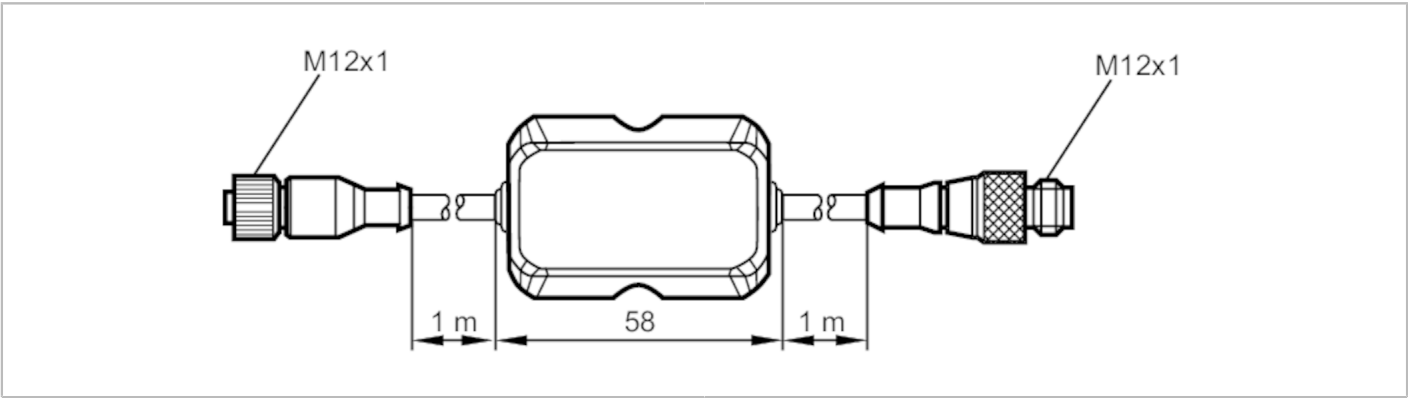

Date electrice		
Tensiunea nominala DC	[V]	9...27
Consum de energie	[mA]	< 500
Clasa de protectie		III
Protectie la polaritate inversa		da
Iesiri		
Protectie la scurtcircuit		da
Condițiile mediului		
Temperatură de ambianță	[°C]	-25...70
Protectie		IP 40
Teste / certificari		
Ecranare electromagnetica	EN 61000-4-2 ESD	4 kV CD / 15 kV AD
	EN 61000-4-3 HF radiat	30 V/m (80...1000 MHz)
	EN 61000-4-4 Burst	2 kV Clește cuplaj
	EN 61000-4-6 HF conductanta	10 V (0,15...80 MHz)
Date mecanice		
Greutate	[g]	151
Materiale		PBT-GF20
Material de etansare		FKM
Observații		
Unitate de ambalare		1 buc.
Conectare electrică - Doză		
Cablul: 1 m, PUR		
Conector: 1 x M12; Corp turnat: TPU, portocaliu; Blocare: alama, nichelată; Etanșare: FKM		

E30406




Convertor de tensiune

VOLTAGE CONVERTER

Conectare electrică

Racord

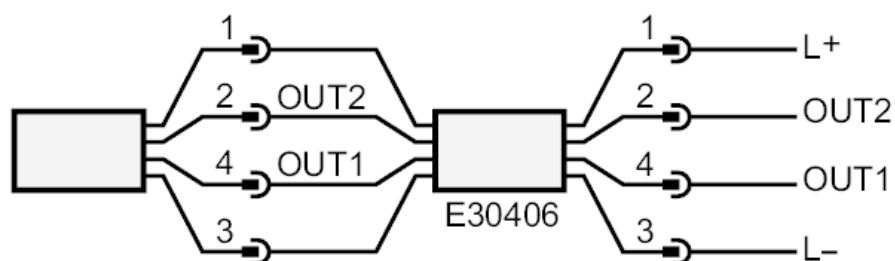

Conectare electrică - mufa

Cablu: 1 m, PUR

Conector: 1 x M12; Corp turnat: TPU, portocaliu; Blocare: alama, nichelată; Etanșare: FKM