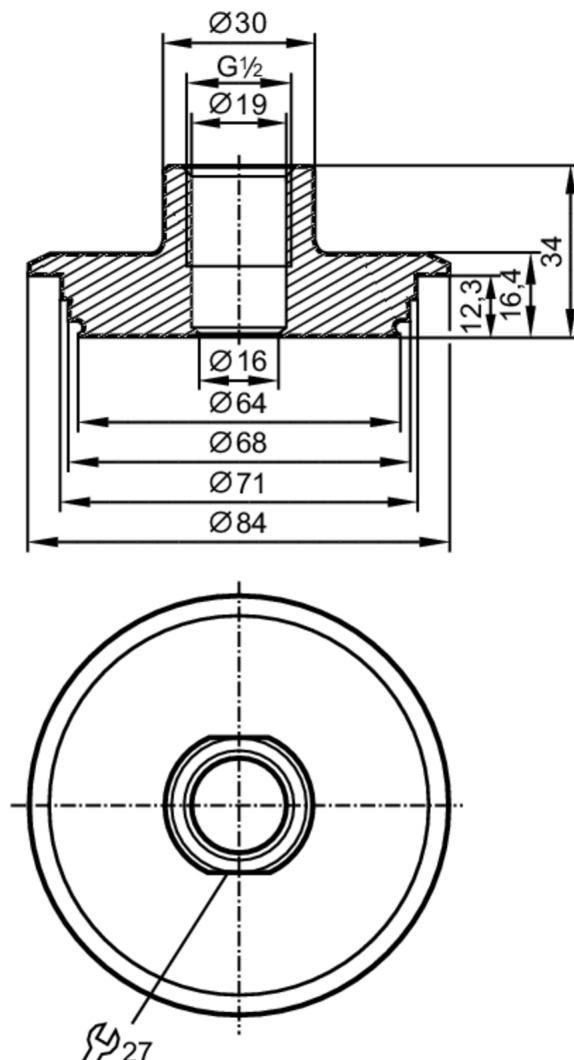


Adaptor de proces Varivent

ADAPT G1/2 VARIVENT D68

EC 1935/2004 EHEDG Tested **FCM** **FDA**

Aplicatie		
Rezistență la presiune	[bar]	25
Date mecanice		
Greutate	[g]	596
Materiale	otel inoxidabil (1.4435 / 316L)	
Conectare senzor	G 1/2 banda de etansare	
Conectarea la proces	Varivent Form N, DN40...DN150 (1,5...6"), Ø 68 mm	
Caracteristicile suprafeței Ra/ Rz a partilor umede	0,4 / 4	
Clasa de echipamente igienice conform DIN 11866	H4	
Observații		
Unitate de ambalare	1 buc.	