




Licence for the operation of moneo in virtualisation environments

moneo vAppliance License

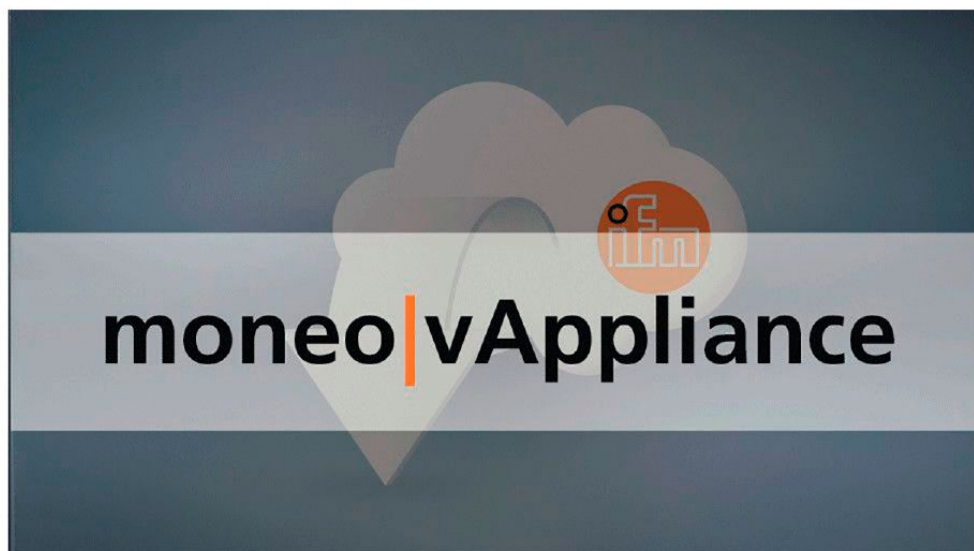

Aplicatie	
Aplica#ie	Virtual appliance for operating the moneo software in an existing IT infrastructure software moneo preinstalat incl. sistem de management pentru mentenan#a aparatului
Configurare	Integration of the .OVF file into the virtualisation environment and subsequent configuration in the AMS (appliance management system)
Compatibilitate	VMware vSphere 7.0 or more recent version Microsoft Hyper-V 2019 sau o versiune mai recentă
Conectivitate	interfe#e pentru senzor #i re#eaua IT
Între#inere #i asisten#ă	incl. mentenan#ă #i asisten#ă până la finalul anului următor
Software / Programare	
Limba	engleză
Suport date	Descărcare

**Licence for the operation of moneo in virtualisation environments**

moneo vAppliance License

Tipul de licență	licență unică
Categorie licență	versiune completă
Condiții sistem	
Cicluri minime CPU	1,8 GHz
Numar minim pentru nuclee CPU	4
Min. RAM	8 GB
Rezoluție grafică minimă	1920 x 1080
Network card	2 x Ethernet 1 Gbit
Network protocol	Ethernet TCP/IP
Sistem de operare	VMware vSphere 7.0; Microsoft Hyper-V 2019; (or more recent version)
Navigator Web	Google Chrome; Mozilla Firefox; (versiuni compatibile: a se vedea notele de lansare actuale)
Observații	
Observații	licențele necesare pentru funcționarea produselor moneo trebuie comandate separat