


ANT860



RFID-UHF-antenn

DTRUHF_AGRWKOTN04

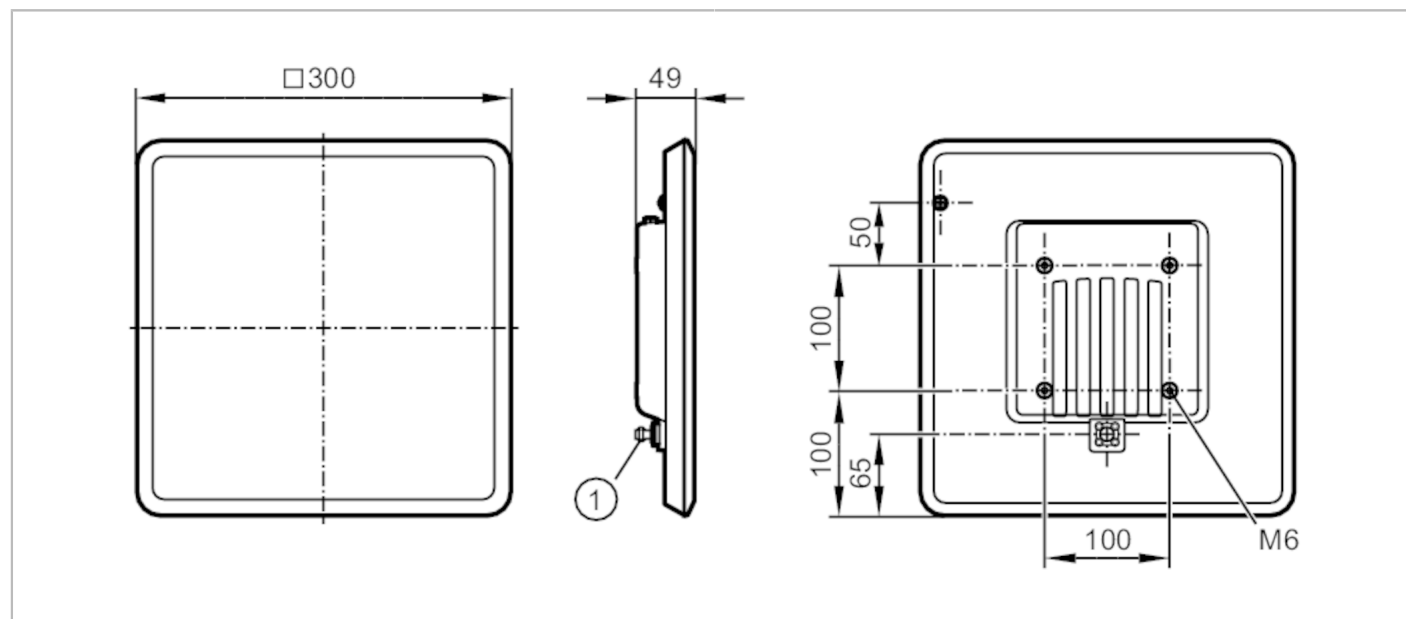

Elektriska data

Arbetsfrekvens	[MHz]	865...868 (ETSI); (Indien: 865...867 MHz)
Antennanslutningar		1; (TNC-honkontakt)
Polarisering		cirkulär
Sändeffekt ERP	[mW]	1995
Antennförstärkning	[dB]	8,5
Impedans	[Ω]	50

Område

Öppningsvinkel	[°]	65
----------------	-----	----

Driftförhållanden

Omgivningstemperatur	[°C]	-40...70
Lagringstemperatur	[°C]	-40...85
Kapslingsklass		IP 67

Mekaniska data

Vikt	[g]	2395,5
Hölje		rektangulär
Mått	[mm]	300 x 300 x 79
Material		kapsling: Aluminium; TNC-honkontakt: Mässing / PTFE; Skyddshölje: plast;

Anmärkning

Förpackning		1 antal
-------------	--	---------