


E12556



Anslutningskabel

VDOGS040PLS0001H04DOGS040PLS

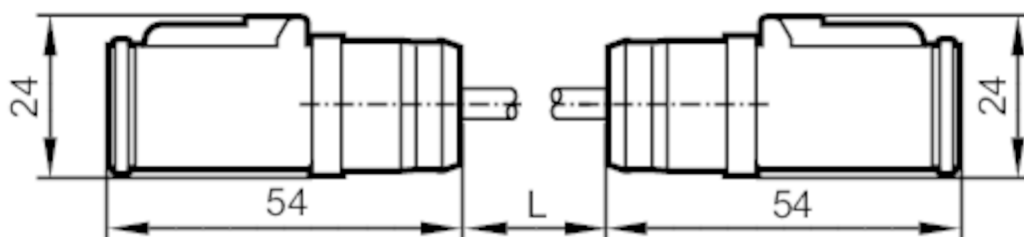

Applikation		
Speciella egenskaper		Silikonfri; Halogenfri
Silikonfri		ja
Elektriska data		
Anslutningsspänning	[V]	12...24 DC
Skyddsklass		III
Max. strömbelastning totalt	[A]	4
Driftförhållanden		
Omgivningstemperatur	[°C]	-40...85
Omgivningstemperatur (rörlig)	[°C]	-30...70
Kapslingsklass		IP 67; (parningskontakt isatt)
Mekaniska data		
Vikt	[g]	119
Gjuten-body material		PA
Anmärkning		
Förpackning		1 antal



Anslutningskabel

VDOGS040PLS0001H04DOGS040PLS

Elektrisk anslutning

kabel: 1 m, PUR, Halogenfri, violett, Ø 6,4 mm; vriden; 2 x 0,50 mm² (28 x 0,15 mm) + 2 x 1 mm² (52 x 0,15 mm)

Elektrisk anslutning - Honkontakt

Anslutning: 2 x DEUTSCH-kontakt, rak; Gjuten kåpa: PA; Kontakter: förnicklad



Anslutning

