


Anslutningskabel hona

ADOGK170MSL005B17

Artikeln ej längre tillgänglig - Arkiv

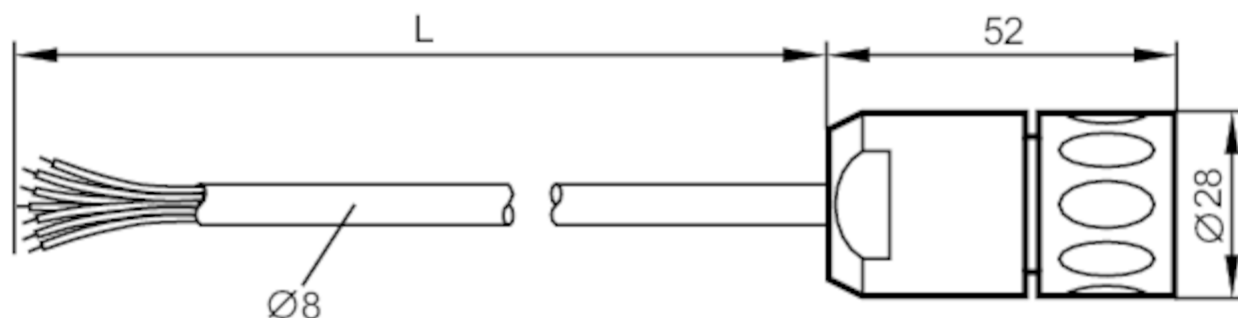

Elektriska data

Anslutningsspänning	[V]	4,5...30 DC
---------------------	-----	-------------

Driftförhållanden

Omgivningstemperatur	[°C]	-10...85
Kapslingsklass		IP 67

Mekaniska data

Vikt	[g]	550
Mått	[mm]	28 x 28 x 52
Material		Mässing plastmantlad; PA 6.6 svart
Gjuten-body material		mässing / PA 6.6, plastmantlad
Material mutter		Mässing, plastmantlad / PA 6.6, plastmantlad

Anmärkning

Förpackning	1 antal
-------------	---------



Anslutningskabel hona

ADOGK170MSL005B17


Elektrisk anslutning

kabel: 5 m, PUR, Ø 8 mm; 13 x 0,14 mm² + 4 x 0,5 mm²

Elektrisk anslutning - Honkontakt

Anslutning: 1 x M23, rak; Gjuten kåpa: mässing / PA 6.6, plastmantlad; Låsning: Mässing, plastmantlad

Anslutning: 1 x M23, rak; Gjuten kåpa: mässing / PA 6.6, plastmantlad; Låsning: PA 6.6, plastmantlad

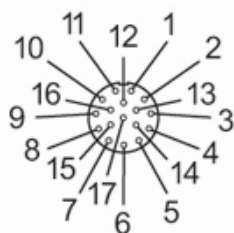

Anslutning

1	BU
2	BK
3	RD
4	WH
5	GN
6	BN
7	BN/GN
8	VT
9	YE
10	WH/GN
11	screen
12	BU/BK
13	RD/BK
14	GY
15	GN/BK
16	YE/BK
17	PK

	Ledarfärger :
BK =	svart
BN =	brun
BU =	blå
GN =	grön
GY =	grå
PK =	rosa
RD =	röd
VT =	violett
WH =	vit
YE =	gul
screen =	Skärm