


RFID tag

ID-TAG/51x48x12,6/04

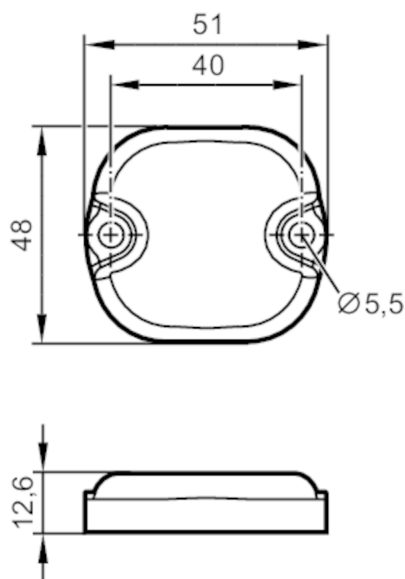

Applikation

Applikation

RFID-kodning av metalltankar

Elektriska data

Arbetsfrekvens	[MHz]	860...930
Minnesstorlek	[bit]	512
Minnestyp		EEPROM
Chiptyp		Impinj Monza 4QT
Tagg identifierare (TID)	[Byte]	8
Elektronisk produkt kod (EPC)		128 bit
RFID-standard		EPC Class1 GEN2/ISO 18000-6C
Max. läscykler		obegränsat
Max. skrivcykler		100000

Driftförhållanden

Omgivningstemperatur	[°C]	-40...85
Lagringstemperatur	[°C]	-40...85
Kapslingsklass		IP 68

Mekaniska data

Vikt	[g]	126,3
Mått	[mm]	48 x 51 x 12,6
Material		kapsling: polykarbonat-ABS

Anmärkning

Förpackning		5 antal
-------------	--	---------

E80414



RFID tag

ID-TAG/51x48x12,6/04

Ytterligare data

läsavstånd (m)

DTE80x	1,2
DTE90x	-
ANT860 / ANT960	3
ANT820 / ANT920	1