


E80415



RFID tag

ID-TAG/10,1X3,9/03 (10 pieces)

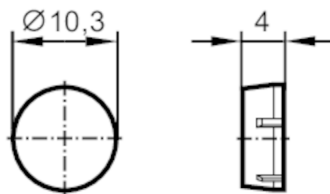

monteringshål: Ø 10,0 x 3,7 mm



Applikation		
Driftstemperatur (aktiv)	[°C]	-40...85
Topptemperatur (passiv)	[°C]	90
Elektriska data		
Arbetsfrekvens	[MHz]	13,56
Minnesstorlek	[bit]	896
Minnestyp		EEPROM
Chiptyp		ICODE SLIX
Antal block		28
Blockstorlek	[Byte]	4
Unikt identifikationsnummer (UID)	[Byte]	8
RFID-standard		ISO 15693
Max. läscykler		obegränsat
Max. skrivcykler		100000
Driftförhållanden		
Omgivningstemperatur	[°C]	-40...85
Lagringstemperatur	[°C]	-40...90
Kapslingsklass		IP 68
Godkännanden / tester		
Radiogodkännande		ISO 15693
Mekaniska data		
Vikt	[g]	5,4
Monteringstyp		Presspassningshus; Installation i metall
Mått	[mm]	Ø 10,3 / L = 4
Material		kapsling: PPS GF30; epoxy
Anmärkning		
Förpackning		10 antal