


E80353



RFID tag

ID-TAG/R30X10/04

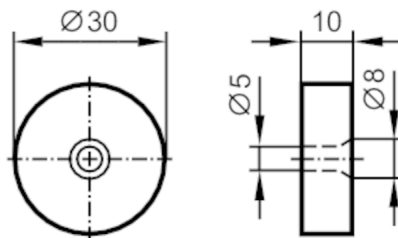

Applikation

Driftstemperatur (aktiv)	[°C]	-25...85
Topptemperatur (passiv)	[°C]	100

Elektriska data

Arbetsfrekvens	[MHz]	865...870
Minnesstorlek	[bit]	128
Max. läscykler		obegränsat
Max. skrivcykler		100000

Driftförhållanden

Omgivningstemperatur	[°C]	-25...85
Lagringstemperatur	[°C]	-40...100

Mekaniska data

Vikt	[g]	8,75
Mått	[mm]	Ø 30 / L = 10
Material		PU svart

Anmärkning

Förpackning		1 antal
-------------	--	---------

Ytterligare data

läsavstånd (m)

DTE80x	0,5
DTE90x	-
ANT860 / ANT960	-
ANT820 / ANT920	-