


E80394



RFID tag

ID-TAG/174x70x17.6/04

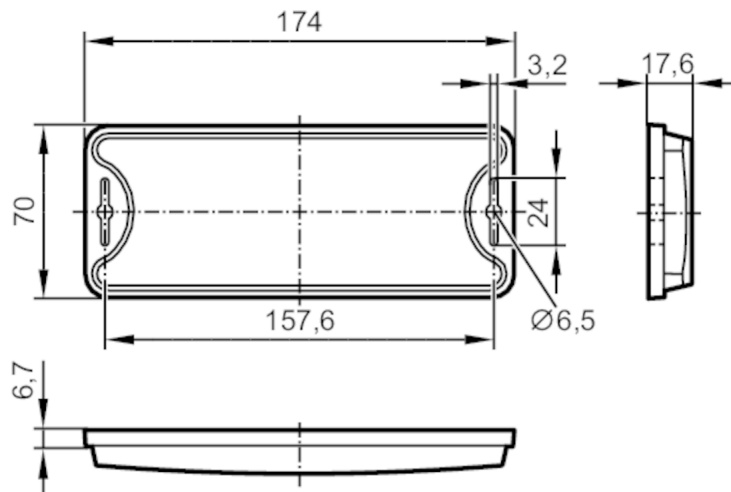

Applikation

Applikation	RFID-kodning av metalltankar
-------------	------------------------------

Elektriska data

Arbetsfrekvens	[MHz]	860...930; (Indien: 865...867 MHz)
Minnesstorlek	[bit]	512
Minnestyp		EEPROM
Chiptyp		Impinj Monza 4QT
Tagg identifierare (TID)	[Byte]	64
Elektronisk produkt kod (EPC)		96 bit; (expanderbar: 128 Bits)
RFID-standard		EPC Class1 GEN2/ISO 18000-6C
Max. läscykler		obegränsat
Max. skrivcykler		100000

Driftförhållanden

Omgivningstemperatur	[°C]	-40...85
Lagringstemperatur	[°C]	-40...100
Kapslingsklass		IP 68

Mekaniska data

Vikt	[g]	129,4
Mått	[mm]	70 x 174 x 17,6
Material		kapsling: polykarbonat-ABS

Anmärkning

Förpackning	1 antal
-------------	---------

E80394



RFID tag

ID-TAG/174x70x17.6/04

Ytterligare data

läsavstånd (m)

DTE80x	3
DTE90x	3,3
ANT860 / ANT960	9
ANT820 / ANT920	2