


# AC2606



## AS-Interface control cabinet module

AnalogModule 4AI Pt100 ST

Article no longer available - archive entry

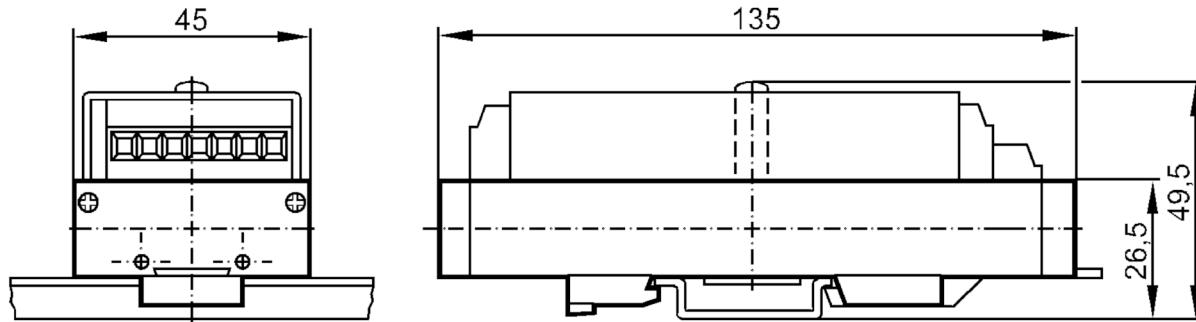

### Product characteristics

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

Measuring range	[°C]	-200...850
-----------------	------	------------

### Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Current consumption	[mA]	< 90
---------------------	------	------

### Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

### Inputs

Number of digital inputs	4
--------------------------	---

Sensor supply of the inputs	AS-i
-----------------------------	------

Max. total current rating of inputs	[mA]	1
-------------------------------------	------	---

Digital inputs protected against short circuits	yes
---	-----

Resolution of analogue input	16 / 0.1 °C
------------------------------	-------------

### Outputs

Electrical design	AS-i
-------------------	------

### Measuring/setting range

Measuring range	[°C]	-200...850
-----------------	------	------------

### Operating conditions

Ambient temperature	[°C]	0...70
---------------------	------	--------

# AC2606



## AS-Interface control cabinet module

AnalogModule 4AI Pt100 ST

Protection	IP 20
<b>AS-i classification</b>	
AS-i profile	S-7.1
AS-i I/O configuration	[hex] 7
AS-i ID code	[hex] 1
<b>Mechanical data</b>	
Type of mounting	mounting on DIN rail and panel; string mounting possible
Materials	PA; PVC
<b>Displays / operating elements</b>	
Display	operation LED, green
<b>Accessories</b>	
Accessories (optional)	LCD display:, E70206
<b>Remarks</b>	
Pack quantity	1 pcs.
<b>Electrical connection</b>	
screw terminals:	
Connection	

