


## AS-Interface insulation monitor

Insulation Monitoring Device

Article no longer available - archive entry

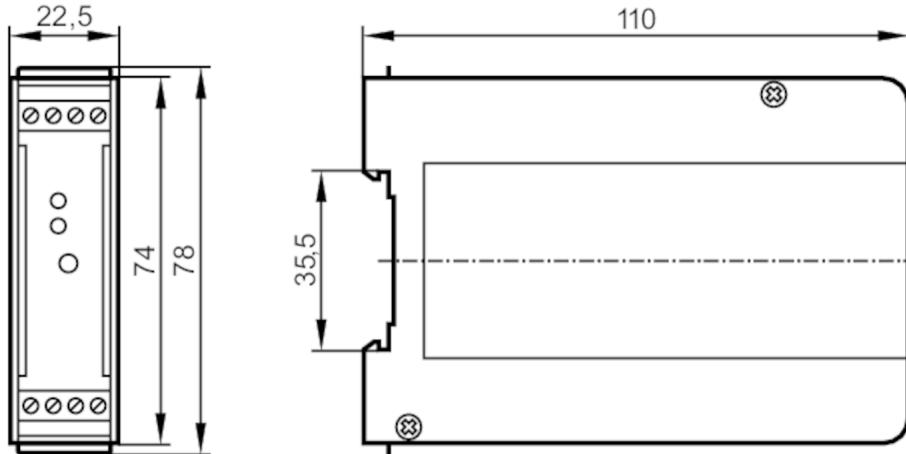

### Application

Application	detection of symmetric and asymmetric insulation faults; insulation monitoring in unearthing AS-i and 24 V DC systems (IT system)
-------------	-----------------------------------------------------------------------------------------------------------------------------------

### Electrical data

Operating voltage	[V]	26.5...31.6 DC
Nominal voltage DC	[V]	21...36
Max. current consumption from AS-i	[mA]	40

### Outputs

Contact rating	1A AC/DC
----------------	----------

### Operating conditions

Ambient temperature	[°C]	-25...60
Storage temperature	[°C]	-40...70
Protection		IP 20

### Tests / approvals

EMC	EN 61557-8	(1997)
	EN 61326/A2	(2001)

### AS-i classification

AS-i certificate	19901
------------------	-------

### Mechanical data

Weight	[g]	179
Housing	mounting on DIN rail and panel	

### Displays / operating elements

Display	operation	LED, green
	function	LED, yellow

# AC2212



## AS-Interface insulation monitor

Insulation Monitoring Device

### Remarks

Remarks	Aktives symmetrisches und passives Messverfahren. 2 Meldekontakte Kontakt 11/14 löst bei unsymmetrischen Fehlern aus. Kontakt 11/24 löst bei symmetrischen und unsymmetrischen Fehlern aus. Kontakt geschlossen wenn AS-i Spannung anliegt und kein Erdschluss vorliegt.
Pack quantity	1 pcs.

### Electrical connection

Connection
------------

