

# DN0512




## Switching amplifier

N605/110VAC/0,8A

Article no longer available - archive entry

Alternative article: DN1020 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

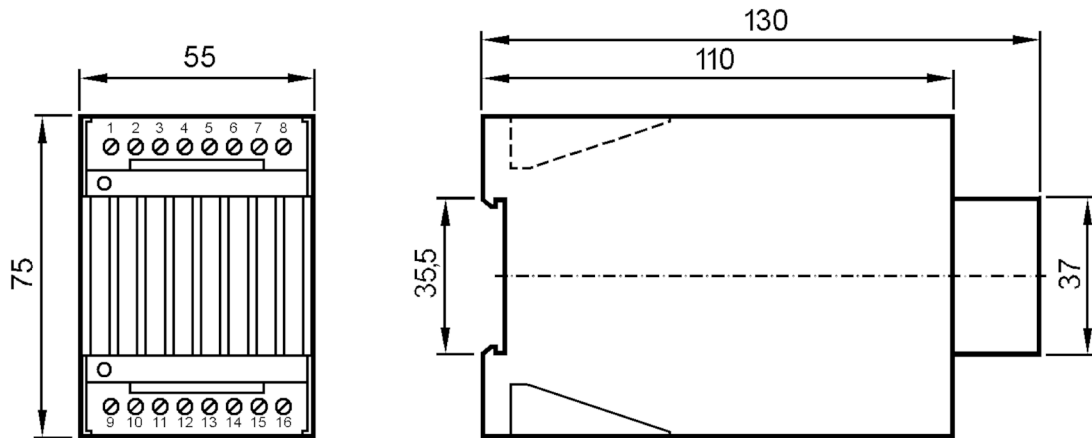

### Electrical data

Nominal frequency AC	[Hz]	47...63
Output voltage	[V]	set
Output voltage tolerance	[%]	5
Max. output current at min. output voltage	[A]	0.8
Number of output circuits		1

### Outputs

Short-circuit protection	yes
Overload protection	yes

### Operating conditions

Ambient temperature	[°C]	0...50
Protection		IP 40

### Mechanical data

Materials	plastics
-----------	----------

### Displays / operating elements

Display	Output voltage	2 x LED, green
---------	----------------	----------------

### Remarks

Pack quantity	1 pcs.
---------------	--------

# DN0512




## Switching amplifier

N605/110VAC/0,8A

### Electrical connection

terminals: ...4 mm<sup>2</sup>

### Connection

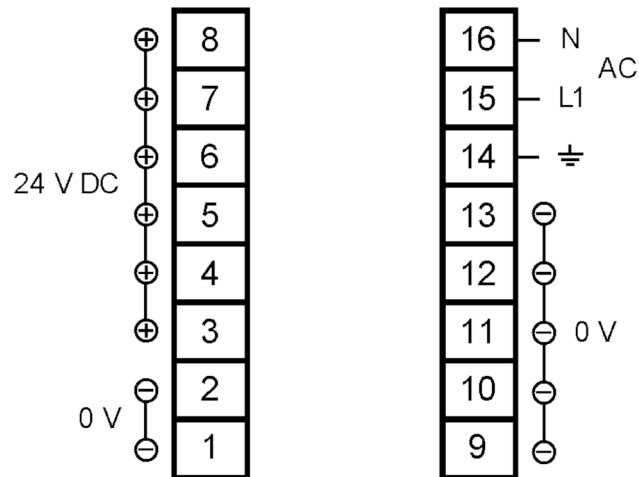

Article no longer available - archive entry

Alternative article: DN1020 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!