




Connecting cable with socket

ADOGH040SCS0005F03

Article no longer available - archive entry

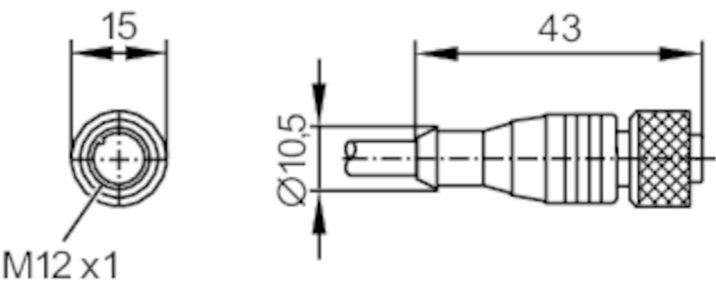

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)	

Electrical connection - socket	
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Tightening torque: 0.5 Nm	




E10419



Connecting cable with socket

ADOGH040SCS0005F03

Connection

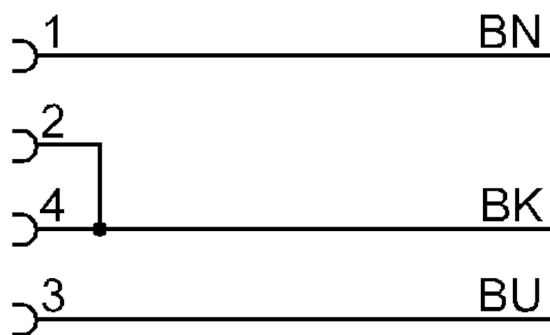

BN =
BK =
BU =

Core colours :
brown
black
blue