


Connecting cable with socket

ADOAH042MSS0010E03

Article no longer available - archive entry

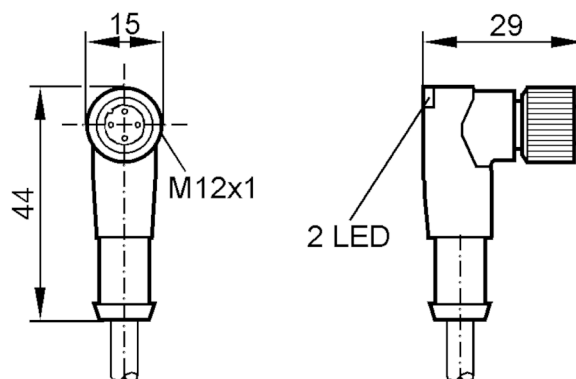

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-20...70
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	29 x 15 x 44
------------	------	--------------

Materials	PA 6.6
-----------	--------

Moulded-body material	PA 6.6
-----------------------	--------

Material nut	aluminium
--------------	-----------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10566



Connecting cable with socket

ADOAH042MSS0010E03

Electrical connection


Cable: 10 m, PUR, orange, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminium



Connection

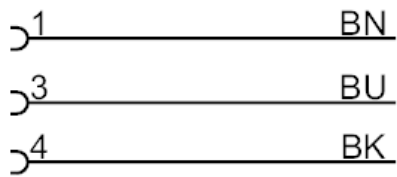

BN =	Core colours :
BK =	brown
BU =	black
	blue