


Connecting cable with socket

ADOAH042MSS0030A03

Article no longer available - archive entry

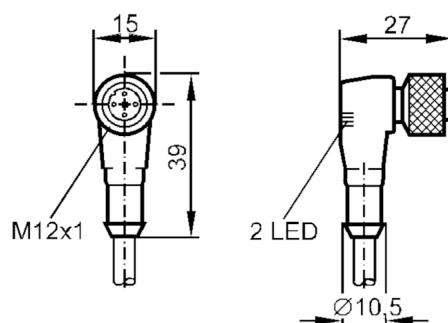

Electrical data

Operating voltage	[M]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	27 x 15 x 39
------------	------	--------------

Materials	TPU transparent
-----------	-----------------

Moulded-body material	TPU, transparent
-----------------------	------------------

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10609



Connecting cable with socket

ADOAH042MSS0030A03

Electrical connection


Cable: 30 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

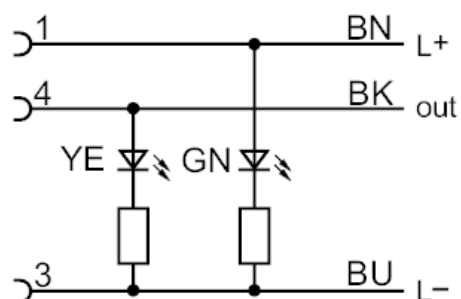

BN =	Core colours :
BK =	brown
BU =	black
	blue