


E10660



Connecting cable with socket

ADOGK190MSS0005B19

Article no longer available - archive entry

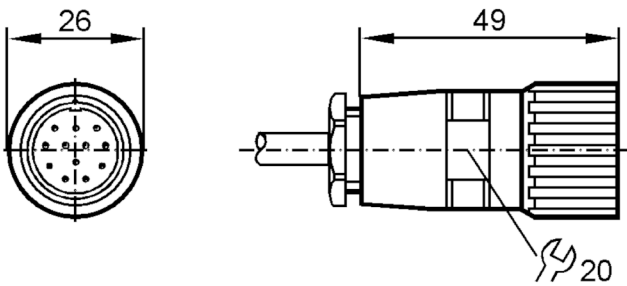

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Protection IP 65

Mechanical data

Dimensions [mm] 26 x 26 x 49

Materials brass nickel-plated

Moulded-body material brass, nickel-plated

Material nut brass, nickel-plated

Remarks


Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PUR; 16 x 0.5 mm² (64 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M23; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

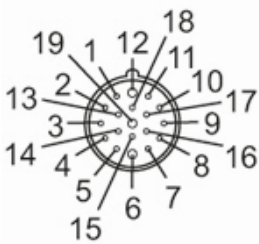

E10660



Connecting cable with socket

ADOGK190MSS0005B19

Connection

1	VT
2	RD
3	GY
4	RD/BU
5	GN
6	BU
7	GY/PK
8	WH/GN
9	WH/YE
10	WH/GY
11	BK
12	GN/YE
13	YE/BN
14	BN/GN
15	WH
16	YE
17	PK
18	GY/BN
19	BN

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow