


E10717



Connecting cable with socket

ADOGH042MSS0005E04

Article no longer available - archive entry

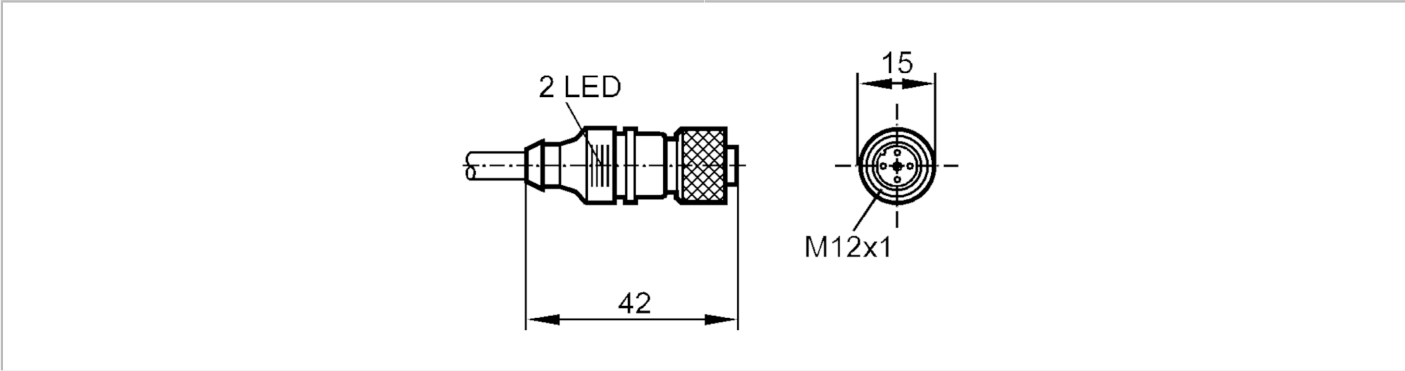

Electrical data

Operating voltage	[M]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 42
Materials		PVC transparent
Moulded-body material		PVC, transparent
Material nut		brass, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC, transparent; Locking: brass, nickel-plated




E10717



Connecting cable with socket

ADOGH042MSS0005E04

Connection

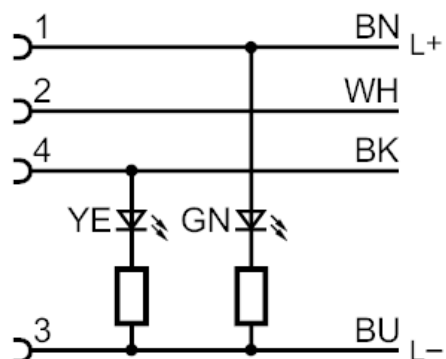

BN =	Core colours :	brown
BK =		black
BU =		blue
WH =		white