




Splitter box

ZDO8F039MSS0005A10

Article no longer available - archive entry

Alternative articles: EBC054

When selecting an alternative article and accessories please note that technical data may differ!

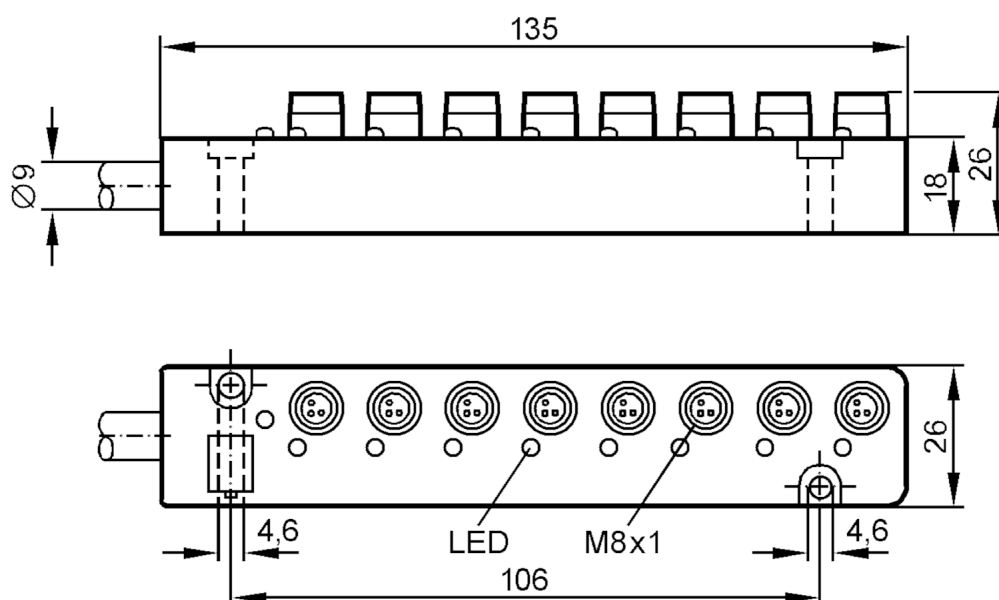

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Number of ports splitter box	8

Displays / operating elements

Display	switching status	8 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10921



Splitter box

 
ZDO8F039MSS0005A10

Electrical connection

Cable: 5 m, PUR / PVC, Halogen-free, black, Ø 9 mm; 8 x 0.34 mm² + 2 x 0.5 mm²

Electrical connection - slot

Connector: 8 x M8; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm



E10921



Splitter box

ZDO8F039MSS0005A10

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow