


E10970



Connecting cable with socket

ADOAF032VAS0010E03

Article no longer available - archive entry

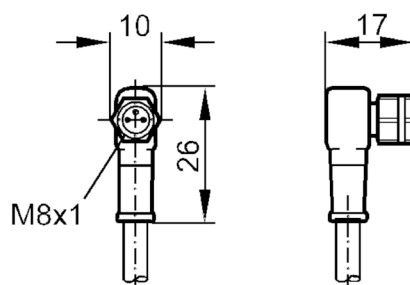

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	TPU transparent
-----------	-----------------

Moulded-body material	TPU, transparent
-----------------------	------------------

Material nut	stainless steel (316L/1.4404)
--------------	-------------------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10970



Connecting cable with socket

 
ADOAF032VAS0010E03

Electrical connection


Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU, transparent; Locking: stainless steel (316L/1.4404)



Connection

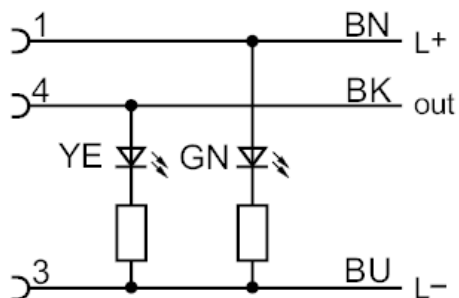

BN =	Core colours :
BK =	brown
BU =	black
	blue