




Connection cable

VDOGH040MSS00,6H04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC026
When selecting an alternative article and accessories please note that technical data may differ!

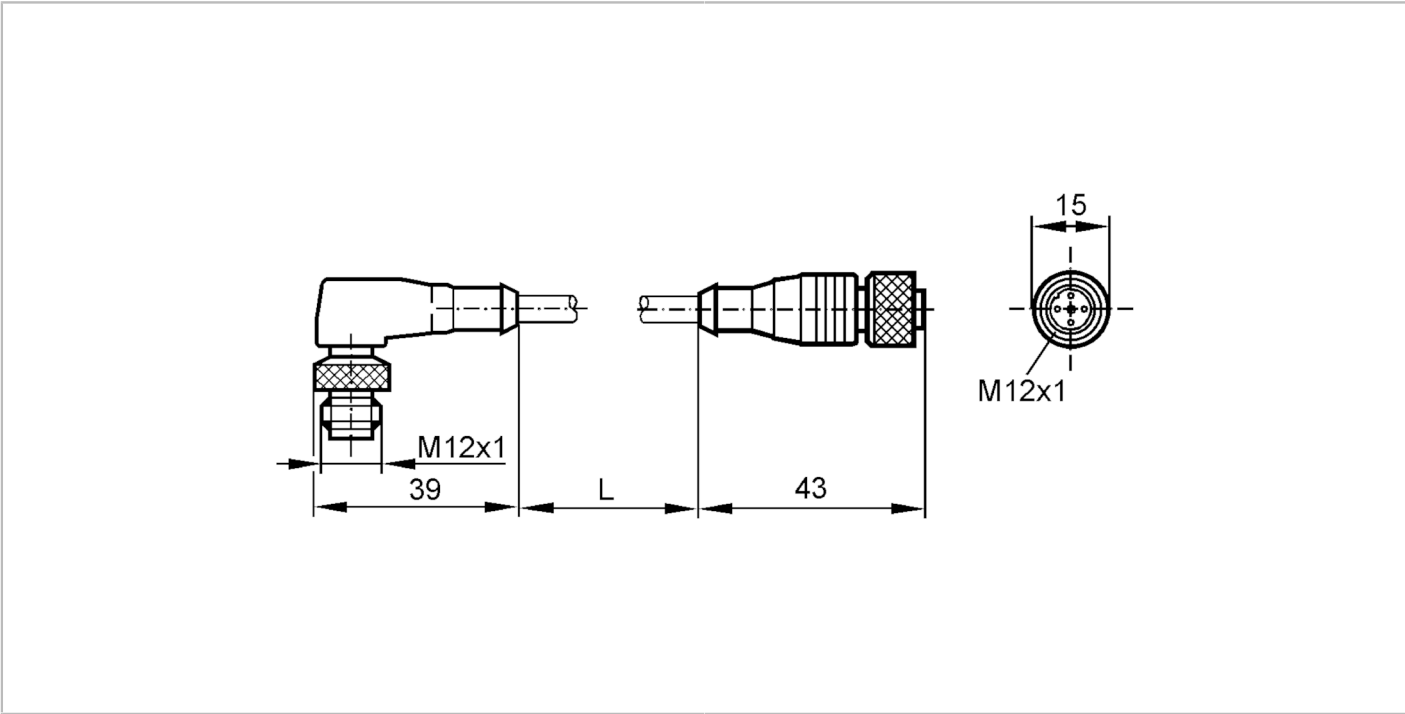

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials PUR

Moulded-body material PUR

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10982



Connection cable

VDOGH040MSS00,6H04STAH040MSS

Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

