


# E10217



## Connecting cable with socket

ADOAG030--S0002E03

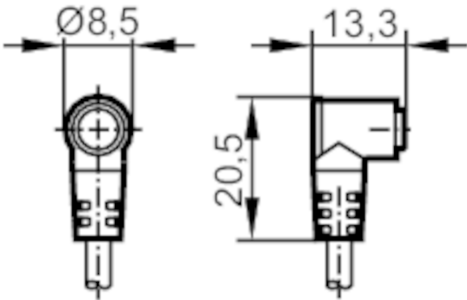

| Electrical data                                               |      |                   |
|---------------------------------------------------------------|------|-------------------|
| Operating voltage                                             | [V]  | < 60 AC/DC        |
| Operating conditions                                          |      |                   |
| Ambient temperature                                           | [°C] | -25...85          |
| Protection                                                    |      | IP 65             |
| Mechanical data                                               |      |                   |
| Weight                                                        | [g]  | 33                |
| Dimensions                                                    | [mm] | 13.3 x 8.5 x 20.5 |
| Materials                                                     |      | PUR               |
| Moulded-body material                                         |      | PUR               |
| Remarks                                                       |      |                   |
| Pack quantity                                                 |      | 1 pcs.            |
| Electrical connection                                         |      |                   |
| Cable: 2 m, PVC, black, Ø 3 mm; 3 x 0.14 mm² (18 x Ø 0.1 mm ) |      |                   |
| Electrical connection - socket                                |      |                   |
| Connector: 1 x M8, angled; coding: A; Moulded body: PUR       |      |                   |
|                                                               |      |                   |

# E10217



## Connecting cable with socket

ADOAG030--S0002E03

### Connection



|      |                |       |
|------|----------------|-------|
| BN = | Core colours : | brown |
| BK = |                | black |
| BU = |                | blue  |