


Wirable plug

SSTGF040MSSFPG

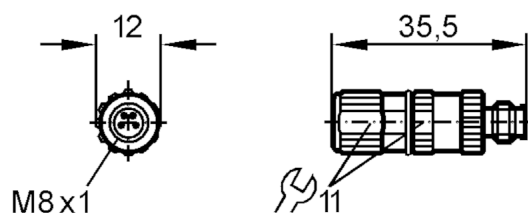

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	14.9
Dimensions	[mm]	12 x 12 x 35.5
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11551



Wirable plug

 
SSTGF040MSSFPG

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

