


E11917



Adapter socket

EDOGH050MSS00,7E05(M16)

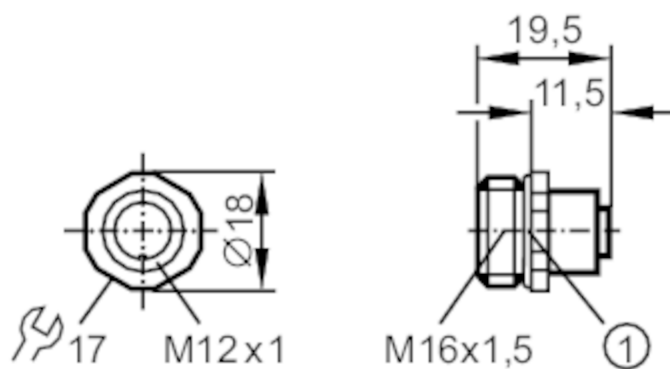

1 O-ring



Electrical data

Operating voltage	[V]	< 125 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...85
---------------------	------	----------

Protection		IP 68
------------	--	-------

Mechanical data

Weight	[g]	25.1
--------	-----	------

Mounting thread		M16
-----------------	--	-----

Materials		diecast zinc nickel-plated
-----------	--	----------------------------

Moulded-body material		diecast zinc, nickel-plated
-----------------------	--	-----------------------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11917



Adapter socket

EDOGH050MSS00,7E05(M16)

Electrical connection


Cable: 0.7 m, PVC; 4 x 0.25 mm² + 1 x 0.5 mm²

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: diecast zinc, nickel-plated



Connection

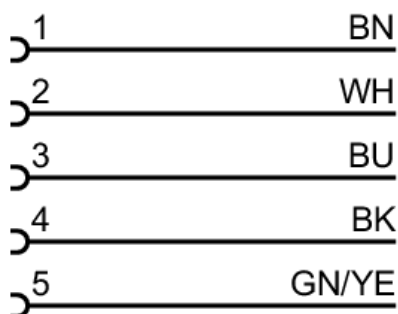

BK =	Core colours :
BN =	black
BU =	brown
GN/YE =	blue
WH =	green/yellow
	white