




Connection cable

VDOAH043MSS00,3H04STGF040MSS

Article no longer available - archive entry

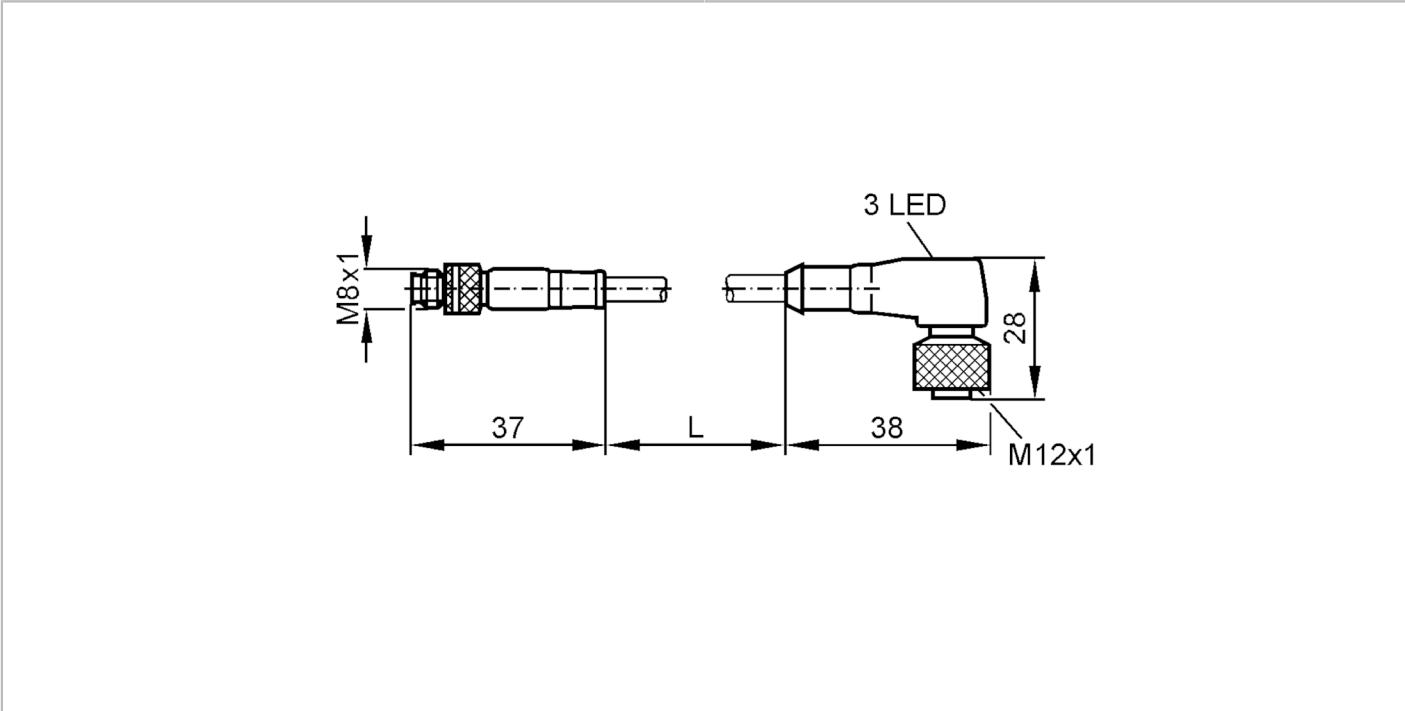

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load total	[A]	3
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection	IP 68	
Mechanical data		
Materials	PUR	
Moulded-body material	PUR	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	

E11371



Connection cable

VDOAH043MSS00,3H04STGF040MSS

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

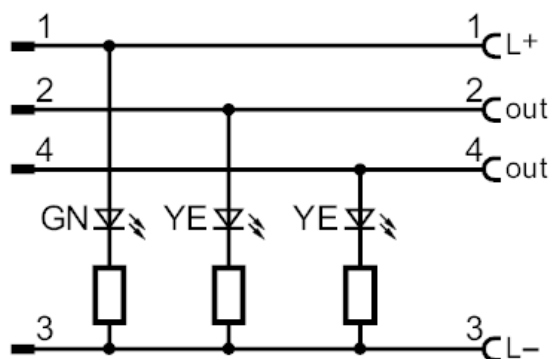

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

