


E12352



Connecting cable with socket

ADOAH050MSS0010K05

Article no longer available - archive entry

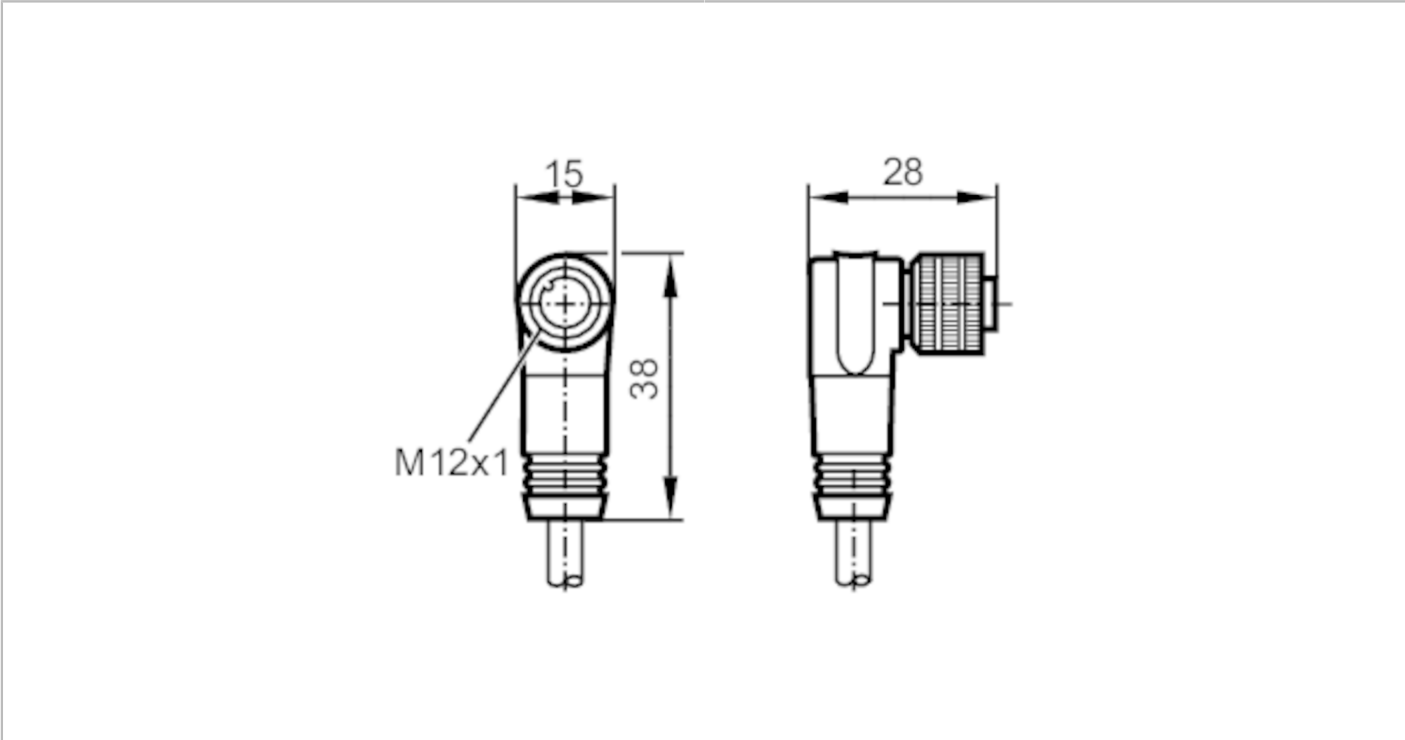

Application		
Special feature		Free from silicone; Gold-plated contacts; Screened cable
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	444.6
Dimensions	[mm]	28 x 15 x 38
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel
Remarks		
Pack quantity		1 pcs.

E12352



Connecting cable with socket


ADOAH050MSS0010K05

Electrical connection


Cable: 10 m, PUR, black, Ø 5.3 mm, shielded; 5 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 1.0...1.5 Nm; Shielded connection cable: screen connected

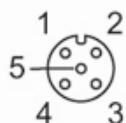

Connection

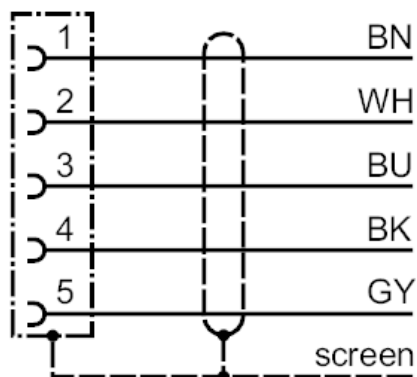

Core colours :	
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white