


Adapter plug

RSTGB030ALS00.3-03

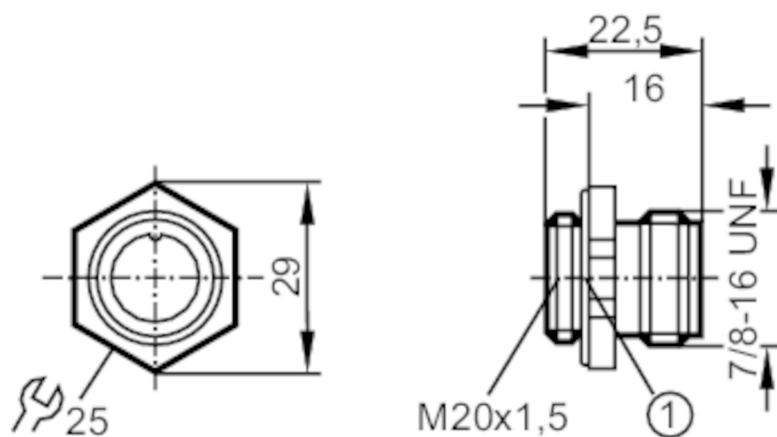

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 600 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...100

Protection

IP 68

Mechanical data

Weight

[g]

36.287

Mounting thread

M20 x 1,5

Materials

brass nickel-plated

Moulded-body material

brass, nickel-plated

Remarks

Pack quantity

 
1 pcs.

Electrical connection

Cable: 0.3 m, PVC; 3 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: brass, nickel-plated; Contacts: gold-plated



E18070



Adapter plug

RSTGB030ALS00.3-03

Connection

1	GN
2	BK
3	WH

BK =	Core colours :
GN =	black
WH =	green
	white