


## Adapter plug

RSTGB050PLS00.3-05

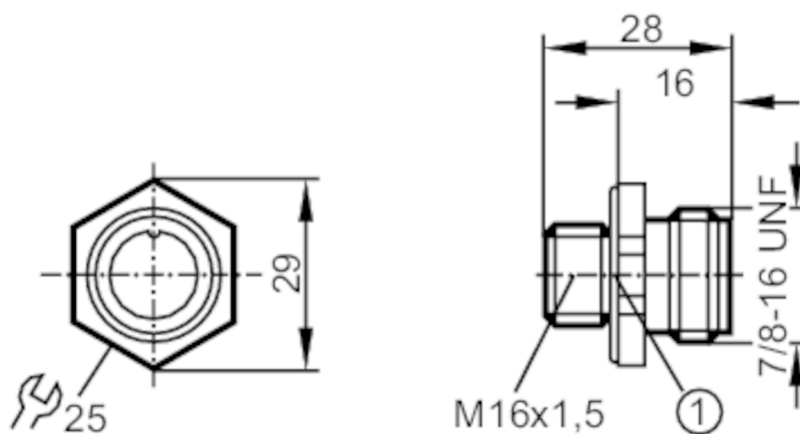

1 O-ring

## Application

|                 |                      |
|-----------------|----------------------|
| Special feature | Gold-plated contacts |
|-----------------|----------------------|

## Electrical data

|                   |     |             |
|-------------------|-----|-------------|
| Operating voltage | [V] | < 600 AC/DC |
|-------------------|-----|-------------|

## Operating conditions

|                     |      |           |
|---------------------|------|-----------|
| Ambient temperature | [°C] | -20...100 |
|---------------------|------|-----------|

|            |       |
|------------|-------|
| Protection | IP 68 |
|------------|-------|

## Mechanical data

|        |     |        |
|--------|-----|--------|
| Weight | [g] | 27.216 |
|--------|-----|--------|

|                 |           |
|-----------------|-----------|
| Mounting thread | M16 x 1,5 |
|-----------------|-----------|

|           |          |
|-----------|----------|
| Materials | plastics |
|-----------|----------|

|                       |          |
|-----------------------|----------|
| Moulded-body material | plastics |
|-----------------------|----------|

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E18072



## Adapter plug


RSTGB050PLS00.3-05

### Electrical connection

Cable: 0.3 m, PVC; 5 x 1.5 mm<sup>2</sup> / AWG 16

### Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: plastics; Contacts: gold-plated

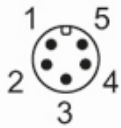

### Connection

|   |    |
|---|----|
| 1 | WH |
| 2 | RD |
| 3 | BU |
| 4 | OG |
| 5 | BK |

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BU = | blue           |
| RD = | red            |
| OG = | orange         |
| WH = | white          |