


Fibre optic diffuse reflection sensor

FT-11-E-A-M6/F2X1/0,6M

Article no longer available - archive entry

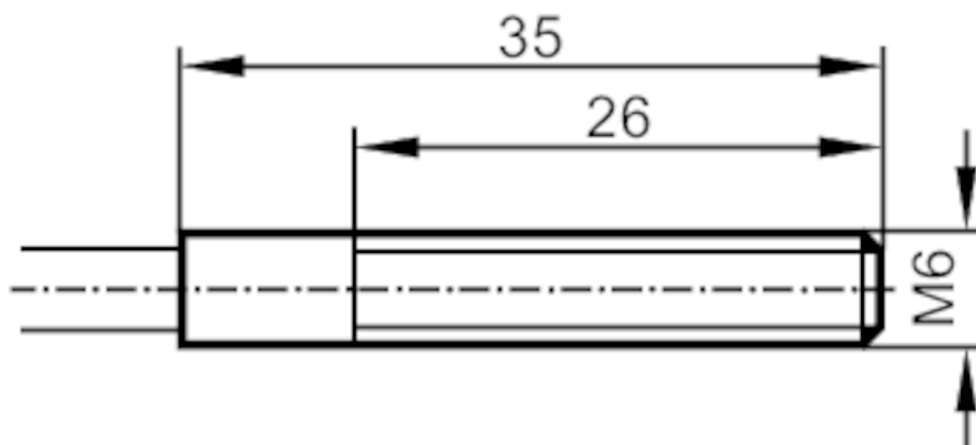

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OBF
---------------------------------------	-----

OBF

Range fibre optics [mm]	70
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...70
--------------------------	----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	600
Min. bending radius [mm]	30
Fibre material	PMMA
Fibre head material	aluminium
Fibre sheath material	PE

E20631



Fibre optic diffuse reflection sensor

FT-11-E-A-M6/F2X1/0,6M

Accessories	
Accessories (optional)	Cutter for fibre optics:, E20600
Remarks	
Pack quantity	1 pcs.