




Fibre optic diffuse reflection sensor

FT-30-A-A-R8/1,2M

Article no longer available - archive entry

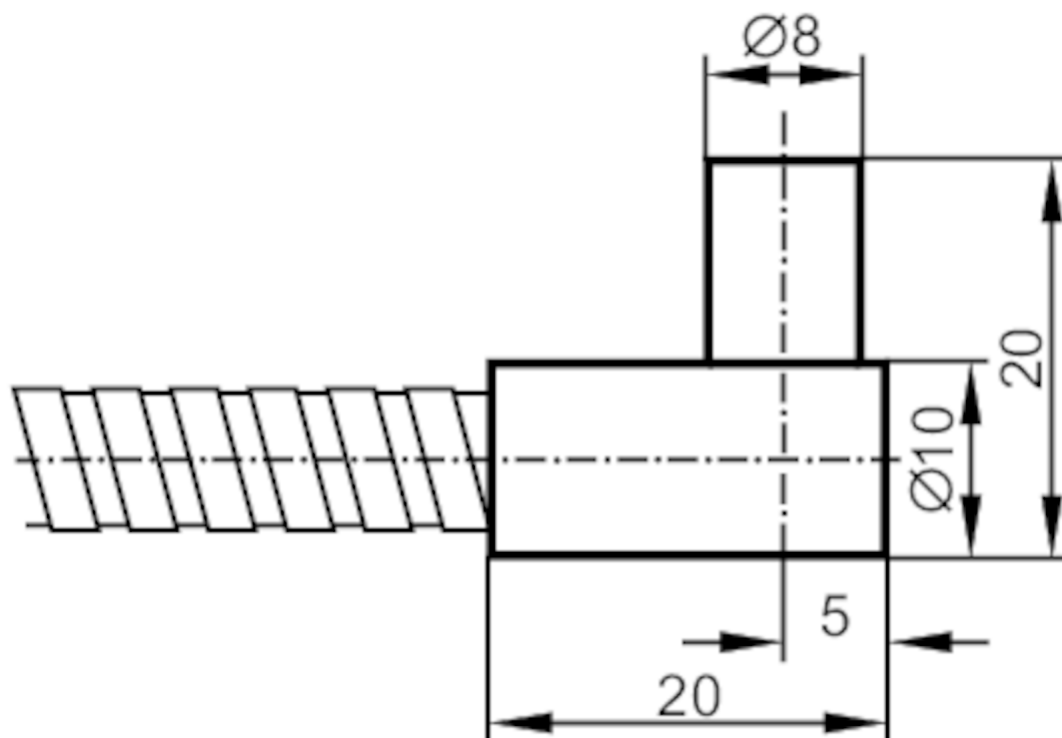

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OIF

OIF

Range fibre optics

[mm]

65

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Total length

[mm]

1200

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

aluminium

Remarks

Pack quantity

1 pcs.