




Fibre optic diffuse reflection sensor

FT-30-P-A-E6/4m

Article no longer available - archive entry

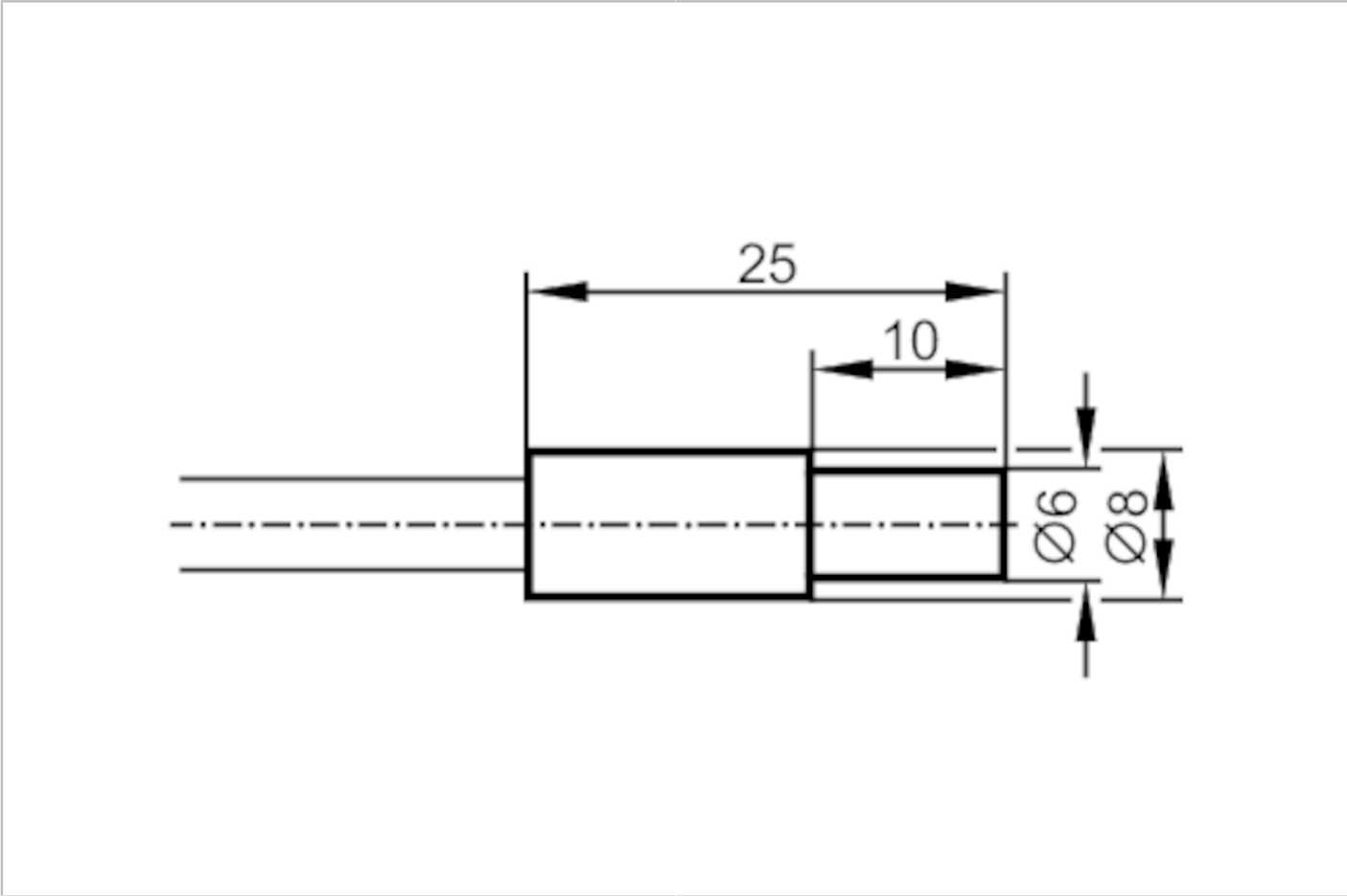

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	20
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	6
Total length [mm]	4000
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC

E20318



Fibre optic diffuse reflection sensor

FT-30-P-A-E6/4m

Remarks	
---------	--

Pack quantity	1 pcs.
---------------	--------