


Fibre optic diffuse reflection sensor

FT-30-P-A-M8/1,5M

Article no longer available - archive entry

Alternative articles: E20221

When selecting an alternative article and accessories please note that technical data may differ!

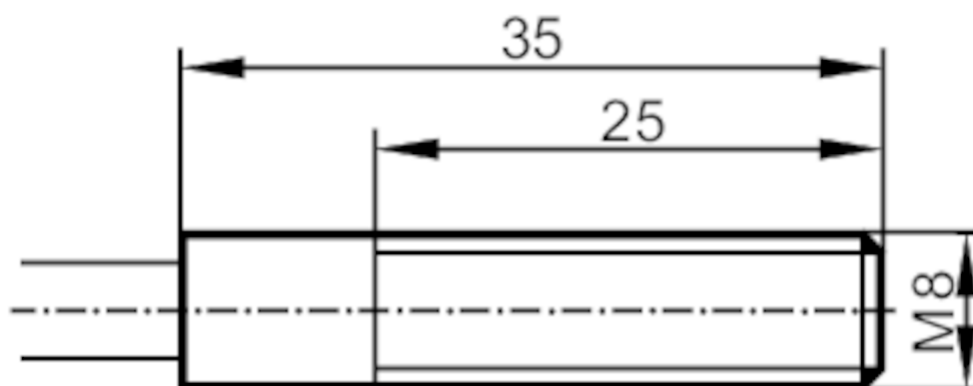

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OIF

OIF

Range fibre optics

[mm]

63

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M8

Total length

[mm]

1500

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

E20398



Fibre optic diffuse reflection sensor

FT-30-P-A-M8/1,5M

Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.