




Dušilni magnet

MAGNET M3.0 HARD FERRITE

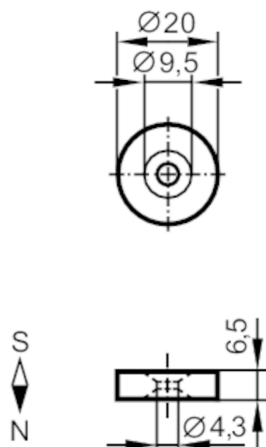

Pogoji okolja

Temperatura okolice	[°C]	-25...250
---------------------	------	-----------

Mehanski podatki

Teža	[g]	10,33
Mere	[mm]	Ø 20 / L = 6,5
Materiali		trdi ferit HF 24/23
Jakost magnetnega polja	[mT]	110

Opombe

Embalažna enota	1 Kosov
-----------------	---------