




Dušilni magnet

MAGNET M4.0 HARD FERRITE

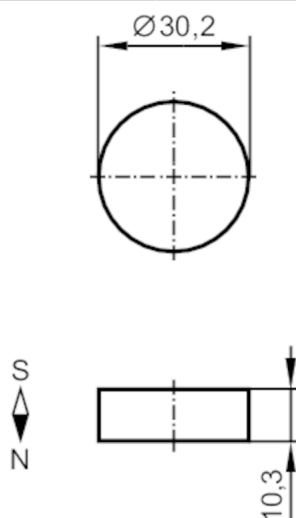

Pogoji okolja

Temperatura okolice	[°C]	-25...250
---------------------	------	-----------

Mehanski podatki

Teža	[g]	37
Mere	[mm]	Ø 30 / L = 10
Materiali		trdi ferit HF 24/23
Jakost magnetnega polja	[mT]	80

Opombe

Embalažna enota	1 Kosov
-----------------	---------