




Dušilni magnet

MAGNET M5.0 HARD FERRITE

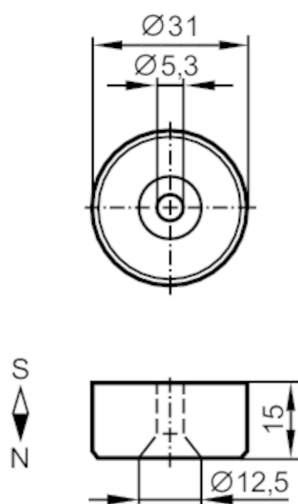

Pogoji okolja

Temperatura okolice	[°C]	-25...250
---------------------	------	-----------

Mehanski podatki

Teža	[g]	53,37
Mere	[mm]	Ø 31 / L = 15
Materiali		trdi ferit HF 26/22
Jakost magnetnega polja	[mT]	120

Opombe

Embalažna enota	1 Kosov
-----------------	---------