


Priključni kabel z vtičnico

ADOGH030MSS0002E03

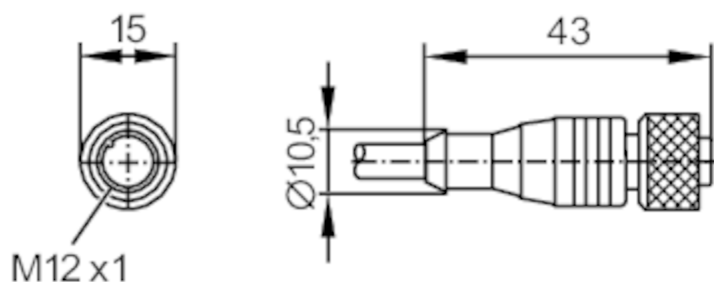

Električni podatki

Obratovalna napetost	[V]	< 250 AC / < 300 DC
----------------------	-----	---------------------

Pogoji okolja

Temperatura okolice	[°C]	-25...90
Zaščita		IP 67

Mehanski podatki

Teža	[g]	87,5
Mere	[mm]	15 x 15 x 43
Materiali		TPU
Material ulitega dela		TPU
Material slepe matice		medenina, ponikljano

Opombe

Embalažna enota		1 Kosov
-----------------	--	---------



Priključni kabel z vtičnico

ADOGH030MSS0002E03

Električni priključek


Kabel: 2 m, PVC, oranžno, Ø 5 mm; 3 x 0,34 mm² (19 x Ø 0,16 mm) / AWG 22

Električni priključek - vtičnica

Spojnik: 1 x M12, ravno; kodiranje: C; Oblikovano telo: TPU; Zaklep: medenina, ponikljano; Pritezni vrtilni moment: 0,5 Nm



Priključek

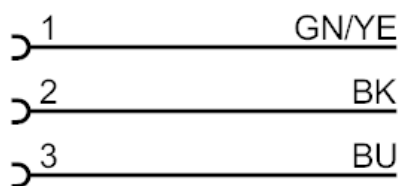

BK =	Barva žil :
BU =	črn
GN/YE =	modro
	zelena/rumena