


## Priključni kabel z vtičnico

ADOGH030MSS0005E03

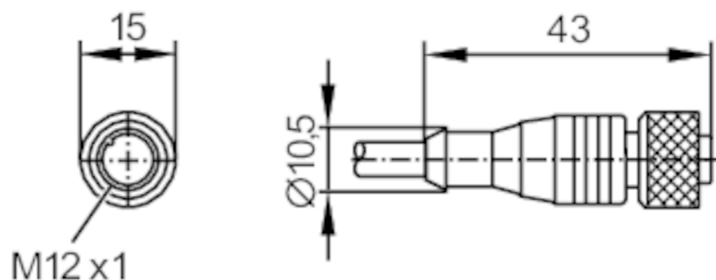

## Električni podatki

|                      |     |                     |
|----------------------|-----|---------------------|
| Obratovalna napetost | [V] | < 250 AC / < 300 DC |
|----------------------|-----|---------------------|

## Pogoji okolja

|                     |      |          |
|---------------------|------|----------|
| Temperatura okolice | [°C] | -25...90 |
| Zaščita             |      | IP 67    |

## Mehanski podatki

|                       |      |                      |
|-----------------------|------|----------------------|
| Teža                  | [g]  | 198,3                |
| Mere                  | [mm] | 15 x 15 x 43         |
| Materiali             |      | TPU                  |
| Material ulitega dela |      | TPU                  |
| Material slepe matice |      | medenina, ponikljano |

## Opombe

|                 |  |         |
|-----------------|--|---------|
| Embalažna enota |  | 1 Kosov |
|-----------------|--|---------|

# E10868



## Priključni kabel z vtičnico

ADOGH030MSS0005E03

### Električni priključek


Kabel: 5 m, PVC, oranžno, Ø 5 mm; 3 x 0,34 mm<sup>2</sup> (19 x Ø 0,16 mm) / AWG 22

### Električni priključek - vtičnica

Spojnik: 1 x M12, ravno; kodiranje: C; Oblikovano telo: TPU; Zaklep: medenina, ponikljano; Pritezni vrtilni moment: 0,5 Nm



### Priključek

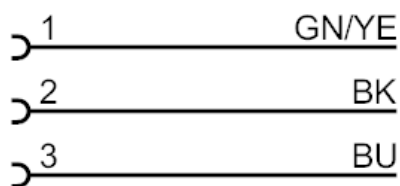

|         |               |
|---------|---------------|
| BK =    | Barva žil :   |
| BU =    | črn           |
| GN/YE = | modro         |
|         | zelena/rumena |