


Vtič adapterja

ESTGH050MSS00,5E05 (M16)

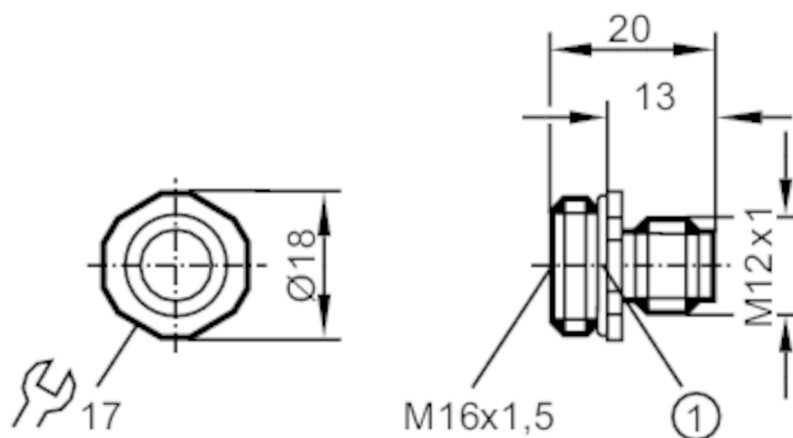

1 O-obroč



Električni podatki

Obratovalna napetost	[V]	< 125 AC/DC
----------------------	-----	-------------

Pogoji okolja

Temperatura okolice	[°C]	-25...85
---------------------	------	----------

Zaščita	IP 68
---------	-------

Mehanski podatki

Teža	[g]	20,3
------	-----	------

Namestitveni navoj	M16
--------------------	-----

Materiali	tlačno litje cinka ponikljano
-----------	-------------------------------

Material ulitega dela	tlačno litje cinka, ponikljano
-----------------------	--------------------------------

Opombe

Embalažna enota	1 Kosov
-----------------	---------



Vtič adapterja


ESTGH050MSS00,5E05 (M16)

Električni priključek

Kabel: 0,5 m, PVC; 5 x 0,25 mm²

Električni priključek - vtič

Spojnik: 1 x M12, ravno; kodiranje: A; Oblikovano telo: tlačno litje cinka, ponikljano

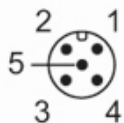

Priključek

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Barva žil :
BK =	črn
BN =	rjava
BU =	modro
GN =	zeleno
WH =	belo
YE =	rumeno