


E11803



Dušilni magnet

MAGNET M4.1/HARD F.STAINLESS

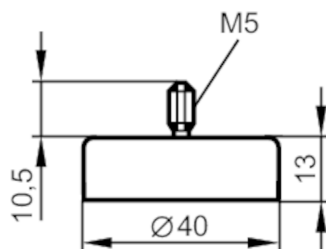

Pogoji okolja

Temperatura okolice	[°C]	-25...200
---------------------	------	-----------

Mehanski podatki

Teža	[g]	79,8
Mere	[mm]	Ø 40 / L = 13
Materiali		Barijev ferit; nerjavno jeklo (1.4571/316Ti)
Jakost magnetnega polja	[mT]	48

Opombe

Embalážna enota	1 Kosov
-----------------	---------