




Pritrdilno tlačno tesnilo

MOUNTING PLATE IND

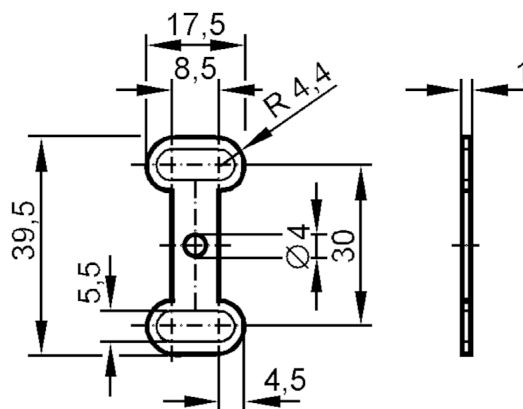

Pogoji okolja

Temperatura okolice	[°C]	-20...60
---------------------	------	----------

Mehanski podatki

Teža	[g]	17
Mere	[mm]	1 x 39,5 x 17,5
Materiali		nerjavno jeklo (1.4571/316Ti)

Pribor

V sklopu dobave	vijak z vtično glavo: 2 x M5 x 35 podložke: 2
-----------------	--

Opombe

Embalážna enota	1 Kosov
-----------------	---------