




Dušilni magnet

MAGNET M6.1 NEODYM, DRILL HOLE

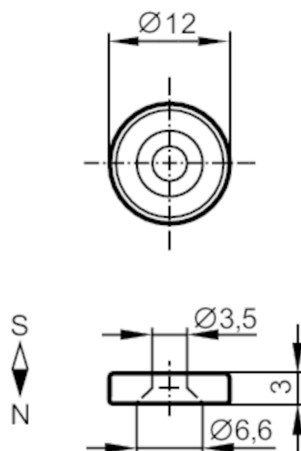

Pogoji okolja

Temperatura okolice	[°C]	-40...80
---------------------	------	----------

Mehanski podatki

Teža	[g]	3
Mere	[mm]	Ø 12 / L = 3
Materiali		neodim
Jakost magnetnega polja	[mT]	250

Opombe

Embalážna enota		1 Kosov
-----------------	--	---------