


E12539



Dušilni magnet

MAGNET M6.0 NEODYM, DRILL HOLE

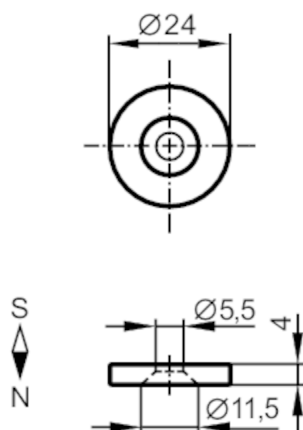

Pogoji okolja

Temperatura okolice	[°C]	-40...80
---------------------	------	----------

Mehanski podatki

Teža	[g]	13
Mere	[mm]	Ø 24 / L = 4
Materiali		neodim
Jakost magnetnega polja	[mT]	240

Opombe

Embalažna enota	1 Kosov
-----------------	---------