


E12541



Dušilni magnet

MAGNET M7.1 NEODYM, SCREW M4

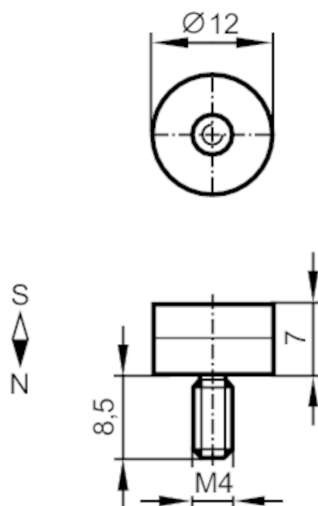

Pogoji okolja

Temperatura okolice	[°C]	-40...80
---------------------	------	----------

Mehanski podatki

Teža	[g]	5,2
------	-----	-----

Mere	[mm]	Ø 12 / L = 7,5
------	------	----------------

Materiali		neodim; plastika
-----------	--	------------------

Jakost magnetnega polja	[mT]	280
-------------------------	------	-----

Opombe

Embalažna enota		1 Kosov
-----------------	--	---------