


E12712



Dušilni magnet

MAGNET M3.1 IATA E12291 5X

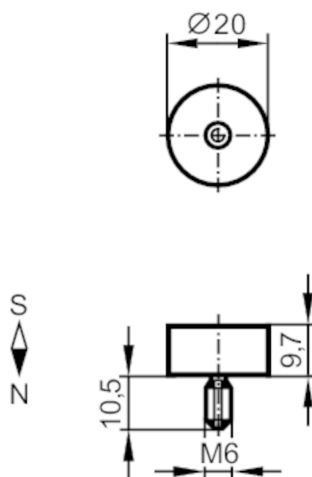

Pogoji okolja

Temperatura okolice	[°C]	-25...250
---------------------	------	-----------

Mehanski podatki

Teža	[g]	162
Mere	[mm]	Ø 20
Materiali	trdi ferit HF 26/22; nerjavno jeklo (1.4571/316Ti)	
Jakost magnetnega polja	[mT]	70

Opombe

Embalažna enota	5 Kosov
-----------------	---------