


E12255



Strnjeni kabel

CABLE/50m/PVC/4x0,34/ORANGE

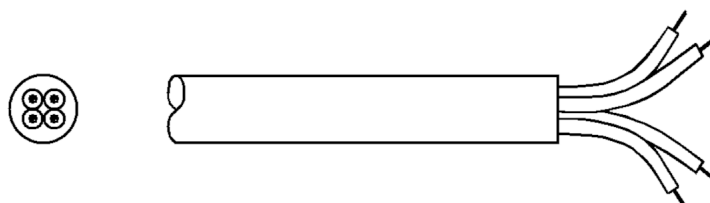

Pogoji okolja

Temperatura okolice	[°C]	-25...100
Temperatura okolja (premikanje)	[°C]	5...100

Mehanski podatki

Teža	[g]	1804,5
------	-----	--------

Opombe

Embalažna enota	1 Kosov
-----------------	---------

Električni priključek

Kabel: 50 m, PVC, oranžno, Ø 4,9 mm; 4 x 0,34 mm² (42 x Ø 0,1 mm)