


E12274



Strnjeni kabel

CABLE/10M/ Silicon/4X0,34/BK

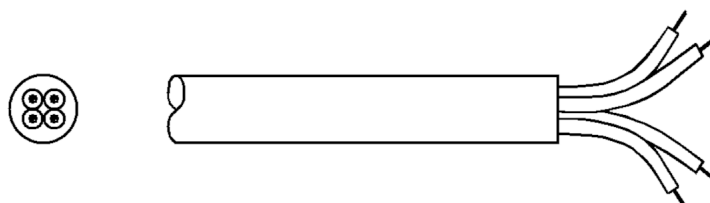

Pogoji okolja

Temperatura okolice	[°C]	-50...180
Temperatura okolja (premikanje)	[°C]	-30...180

Mehanski podatki

Teža	[g]	447,8
------	-----	-------

Opombe

Embalažna enota	1 Kosov
-----------------	---------

Električni priključek

Kabel: 10 m, silikon, črn, Ø 5,4 mm; 4 x 0,34 mm² (19 x Ø 0,15 mm), silikon