


E12291



Dušilni magnet

MAGNET M3.1/HARD F.STAINLESS

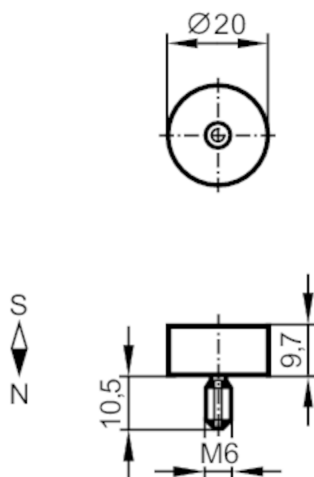

Pogoji okolja

Temperatura okolice	[°C]	-25...250
---------------------	------	-----------

Mehanski podatki

Teža	[g]	22,7
Mere	[mm]	Ø 20
Materiali		trdi ferit HF 26/22; nerjavno jeklo (1.4571/316Ti)
Jakost magnetnega polja	[mT]	70

Opombe

Embalažna enota	1 Kosov
-----------------	---------