


Vtič adapterja

ESTGH040PLS00,5E04 (PG11)

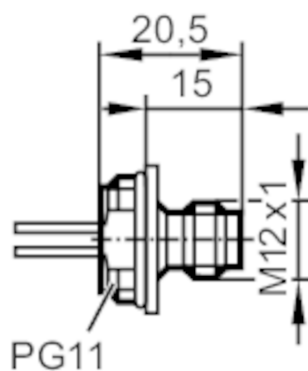

1 O-obroč



Električni podatki

Obratovalna napetost	[V]	< 250 AC/DC
Maks. tokovna obremenitev, skupna	[A]	4; (...40 °C)

Pogoji okolja

Temperatura okolice	[°C]	-40...85
Zaščita		IP 67

Mehanski podatki

Teža	[g]	9,66
Namestitveni navoj		PG 11
Materiali		PA 6.6
Material ulitega dela		PA 6.6

Opombe

Embalažna enota		1 Kosov
-----------------	--	---------



Vtič adapterja

ESTGH040PLS00,5E04 (PG11)

Električni priključek

Kabel: 0,5 m, PVC; 4 x 0,25 mm²

Električni priključek - vtič

Spojnik: 1 x M12, ravno; kodiranje: A; Oblikovano telo: PA 6.6



Priključek

1	BN
2	WH
3	BU
4	BK

BK =	Barva žil :
BN =	črn
BU =	rjava
WH =	modro
	belo