


Vtič adapterja

RSTGH040ALS00.3-04

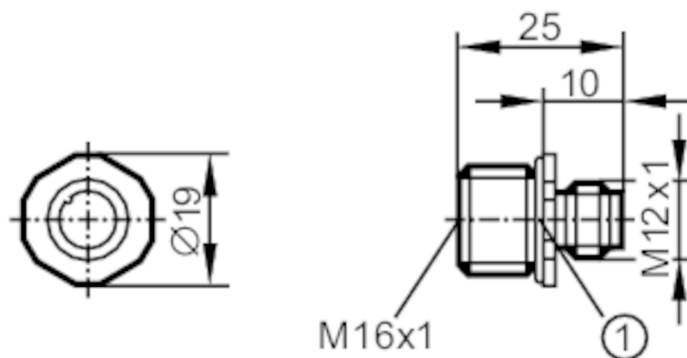

1 O-obroč

Električni podatki

Obratovalna napetost	[V]	< 250 DC
----------------------	-----	----------

Pogoji okolja

Temperatura okolice	[°C]	-20...90
---------------------	------	----------

Mehanski podatki

Teža	[g]	22,68
Namestitveni navoj		M16
Materiali		aluminij anodizirano 10...20 µm
Material ulitega dela		aluminij, anodizirano 10...20 µm

Opombe

Embalažna enota	1 Kosov
-----------------	---------

Električni priključek

Kabel: 0,5 m, PVC; 4 x 0,34 mm² / AWG 22

Električni priključek - vtič

Spojnik: 1 x M12; kodiranje: A; Oblikovano telo: aluminij, anodizirano 10...20 µm



E18073



Vtič adapterja

RSTGH040ALS00.3-04

Priključek

1	BN
2	WH
3	BU
4	BK

	Barva žil :
BK =	črn
BN =	rjavo
BU =	modro
WH =	belo