


# E30437

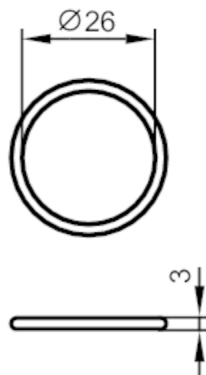

## O-obroč

O-RG 26,00X 3,00/FKM/75/SW



EC 1935/2004 

### Mehanski podatki

|                 |      |     |
|-----------------|------|-----|
| Teža            | [g]  | 2,5 |
| Notranji premer | [mm] | 26  |
| Zunanji premer  | [mm] | 32  |
| Materiali       |      | FKM |

### Opombe

|                 |         |
|-----------------|---------|
| Embalažna enota | 1 Kosov |
|-----------------|---------|